


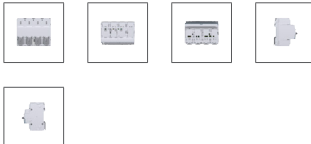

HTG411H



Multi energy data logger & server + micro SD card

Technical Features

Equipment

Web server Yes

Voltage

Operating voltage 24 - 24 V

Type voltage supply DC

Connectivity

Type of interface bus system/media gateway Ethernet interface

Power

Power consumption VA 7 VA

Safety

Ingress Protection (IP) class IP20

Use conditions

Operating temperature -25 - 70 °C

Controls and indicators

With LED indication Yes

Dimensions

Number of width units 6

Sustainability

RoHS conform Yes