


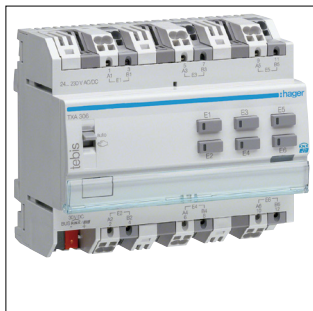

TXA306



Binary input 6 fold, universal, modular, KNX

Technical Features

Architecture

Bus system	EIB
------------	-----

Settings

Supported configuration mode	ETS easy
------------------------------	-------------

Electric current

Number of entry circuits	6
--------------------------	---

Equipment

External signal voltage necessary	No
-----------------------------------	----

Connectivity

With bus system KNX radio	No
---------------------------	----

Equipment

Radio frequency bidirectional	No
-------------------------------	----

With battery	No
--------------	----

With HVAC control	No
-------------------	----

Installation, mounting

Mounting on	DIN rail
-------------	----------

Lighting

LED controlling	No
-----------------	----

Materials

Material	Plastic
----------	---------

Colour	Light grey
--------	------------

RAL code	7035
----------	------

Safety

Ingress Protection (IP) class	IP20
-------------------------------	------

Use conditions

Operating temperature	0 - 45 °C
-----------------------	-----------

Voltage

Input voltage	24 - 230 V
---------------	------------

Operating voltage over bus	21 - 32 V
----------------------------	-----------

Type voltage supply	AC/DC
---------------------	-------

Dimensions

Length	70 mm
--------	-------

Height	90 mm
--------	-------

Depth	60 mm
-------	-------

Texts

Type of connection	With quickconnect plug-in terminals
--------------------	-------------------------------------

Sustainability

RoHS conform	Yes
--------------	-----