


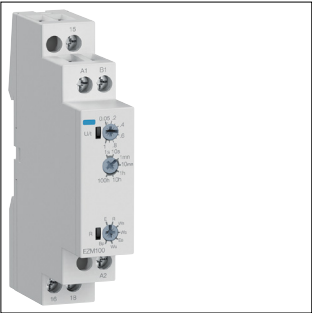

EZM100



Multifunction time relay 12-240V AC/DC

Technical Features

Frequency

Frequency	50 - 60 Hz
-----------	------------

Use conditions

Operating temperature	-25 - 55 °C
Storage/transport temperature	-25 - 70 °C

Connection

Cross-section flexible conductor	0.5 - 2.5 mm ²
Cross-section rigid conductor	0.5 - 2.5 mm ²
Number of contacts	1
Type of contacts	1x changeover

Capacity

Number of modules	1
-------------------	---

Dimensions

Height	87 mm
Width	17.50 mm
Depth	65 mm

Electric current

Acceptable current rating AC1	8 A
-------------------------------	-----

Equipment

Number of NC contacts	1
Number of NO contacts	1
Switch off delay	Yes
Switch on delay	Yes

Settings

Time delay	50 ms - 100 h
------------	---------------

Voltage

Command voltage for 50 Hz	12 - 240 V
Command voltage for 60 Hz	12 - 240 V
Command voltage Us for DC	12 - 240 V
Type voltage supply	AC/DC

Sustainability

Halogen free	Yes
REACH-SVHC free	Yes
RoHS conform	Yes