


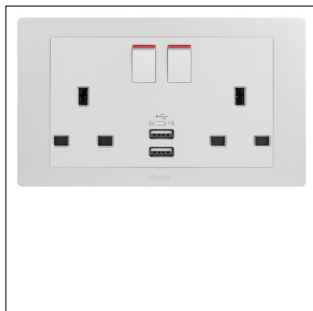

WGMS213SUSBAS

### 13A TWIN SWITCHED SOCKET+2 USB, AS

#### Technical Features

##### Voltage

|               |       |
|---------------|-------|
| Rated voltage | 230 V |
|---------------|-------|

##### Electric current

|                |         |
|----------------|---------|
| Output current | 2400 mA |
| Rated current  | 13 A    |

##### Voltage

|                |       |
|----------------|-------|
| Output voltage | 0-0 V |
|----------------|-------|

##### Use conditions

|                       |           |
|-----------------------|-----------|
| Operating temperature | -20-45 °C |
|-----------------------|-----------|

##### Frequency

|           |            |
|-----------|------------|
| Frequency | 50 - 60 Hz |
|-----------|------------|

##### Power

|                           |        |
|---------------------------|--------|
| Output power              | 0 W    |
| Power consumption standby | 0.15 W |

##### Materials

|                                                        |                    |
|--------------------------------------------------------|--------------------|
| Colour                                                 | Aurora silver      |
| Surface finish                                         | Matt               |
| Material                                               | Polycarbonate (PC) |
| Treatment                                              | Coated             |
| Contains recycled material (% of total plastic weight) | 0 %                |

##### Dimensions

|        |       |
|--------|-------|
| Height | 20 mm |
| Width  | 86 mm |
| Depth  | 20 mm |

##### Cable

|              |     |
|--------------|-----|
| Cable length | 0 m |
|--------------|-----|

##### Dimensions

|                                    |       |
|------------------------------------|-------|
| Built-in depth flush-mounted boxes | 35 mm |
| Built-in depth                     | 20 mm |

##### Connection

|                                                          |                          |
|----------------------------------------------------------|--------------------------|
| Connector/plug type                                      | British Standard         |
| Cross-section flexible conductor without wire end sleeve | 0.08 - 4 mm <sup>2</sup> |

##### Installation, mounting

|                               |                |
|-------------------------------|----------------|
| Mounting on                   | Flush mounting |
| Mounting-/Connection Position | Back           |

##### Connectivity

|                         |                |
|-------------------------|----------------|
| Type of connection      | Screw terminal |
| With claw mounting      | No             |
| Mounting type           | Screw mounting |
| Connector/plug type USB | AA             |

##### Equipment

|                                   |                  |
|-----------------------------------|------------------|
| Connector/plug type socket outlet | British Standard |
| Rotated central insert            | No               |
| With hinged lid                   | No               |
| With round protective earth pin   | No               |
| With signal lamp                  | No               |
| With lock                         | No               |

# Product Datasheet

## WGMS213SUSBAS

---

### Accessories

|                     |      |
|---------------------|------|
| Has labelling field | No   |
| Pre-equipped with   | None |

### Capacity

|                   |   |
|-------------------|---|
| Number of modules | 0 |
|-------------------|---|

### Safety

|                                  |      |
|----------------------------------|------|
| With enhanced contact protection | No   |
| Impact resistance IK             | IK02 |
| Ingress Protection (IP) class    | IP20 |

### Functions

|                           |    |
|---------------------------|----|
| With orientation lighting | No |
| With function lighting    | No |

### Identification

|              |    |
|--------------|----|
| With imprint | No |
|--------------|----|

### Suitable for

|       |  |
|-------|--|
| shark |  |
|-------|--|

### Sustainability

|                 |     |
|-----------------|-----|
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |