


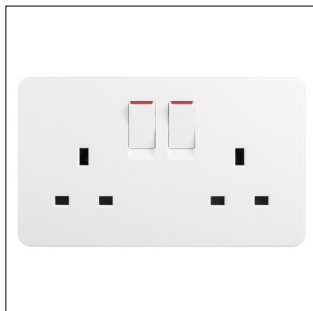

WGDS213SDP

13A TWIN DP SWITCHED SOCKET

Technical Features

Electric current

Rated current	13 A
Output current	0 mA

Voltage

Rated voltage	250 V
Nominal voltage	220-250 V
Output voltage	0-0 V

Use conditions

Operating temperature	-20-45 °C
-----------------------	-----------

Frequency

Frequency	50 - 60 Hz
-----------	------------

Power

Output power	0 W
Power consumption standby	0 W

Materials

Colour	White
Surface finish	Glossy
Material	Polycarbonate (PC)
Treatment	Untreated
Contains recycled material (% of total plastic weight)	0 %

Dimensions

Height	18 mm
Width	86 mm
Depth	18 mm
Built-in depth flush-mounted boxes	35 mm
Built-in depth	18 mm

Connection

Connector/plug type	British Standard
Cross-section flexible conductor without wire end sleeve	0,08 - 4 mm ²

Installation, mounting

Mounting on	Flush mounting
Mounting-/Connection Position	Back

Connectivity

Type of connection	Screw terminal
With claw mounting	No
Mounting type	Screw mounting
Connector/plug type USB	British Standard

Equipment

Connector/plug type socket outlet	British Standard
Rotated central insert	No
With hinged lid	No
With round protective earth pin	No
With signal lamp	No
With lock	No

Accessories

Has labelling field	No
Pre-equipped with	None

Product Datasheet

WGDS213SDP

Capacity	
Number of modules	0
Safety	
With enhanced contact protection	No
Impact resistance IK	IK02
Ingress Protection (IP) class	IP20
Functions	
With orientation lighting	No
With function lighting	No
Identification	
With imprint	No
Suitable for	
shark	
Sustainability	
Halogen free	Yes
REACH-SVHC free	Yes
RoHS conform	Yes