




47403515

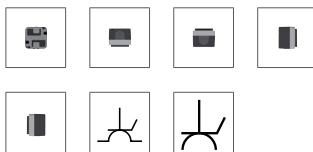

**SCHUKO soc. out. hinged cover surface-mtd, W.1, grey/light grey matt**

**Technical Features**

**Electric current**

Rated current	16 A
---------------	------

**Voltage**

Rated voltage	250 V
Nominal voltage	250 - 250 V

**Use conditions**

Operating temperature	-15 - 30 °C
-----------------------	-------------

**Frequency**

Frequency	50 - 60 Hz
-----------	------------

**Materials**

Colour	Grey
RAL code	7011
Surface finish	Matt
Material	Thermoplastic
Treatment	Untreated
Contains recycled material (% of total plastic weight)	27.8 %

**Dimensions**

Height	76 mm
Width	76 mm
Depth	63 mm
Number of units	1
Built-in depth flush-mounted boxes	0 mm

**Connection**

Conductor cross-section	1.0 - 2.5 mm <sup>2</sup>
-------------------------	---------------------------

**Installation, mounting**

Mounting on	Surface mounting
-------------	------------------

**Connectivity**

Type of connection	Plug-in connection
Mounting type	Screw mounting Claw mounting

**Equipment**

Connector/plug type socket outlet	SCHUKO
Rotated central insert	No
With hinged lid	Yes
With round protective earth pin	No
With signal lamp	No
With lock	No

**Accessories**

Has labelling field	No
---------------------	----

**Cover, door**

Type of lid	Self-closing hinged cover, can be arrested in end position
-------------	--

**Capacity**

Number of modules	1
-------------------	---

**Safety**

With enhanced contact protection	No
Impact resistance IK	IK05
Ingress Protection (IP) class	IP55

<b>Functions</b>		
With orientation lighting		No
With function lighting		No
<b>Texts</b>		
Imprint		Without imprint
Cover		Complete housing
Protection	Without enhanced contact protection	
Type of connection		With plug-in terminals
<b>Sustainability</b>		
Halogen free		Yes
RoHS conform		Yes