


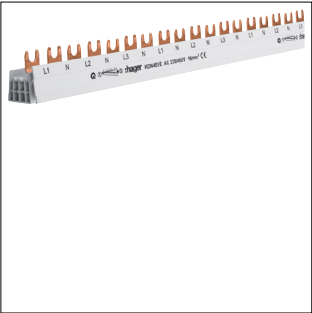

KDN451E

Insulated busbar 3x(P+N) 80A fork 16mm² 54M

Technical Features

Electric current

Rated current	80 A
---------------	------

Architecture

Number of poles	4
Type of pole	3x 1P+N

Dimensions

Length	1000 mm
--------	---------

Voltage

Rated impulse withstand voltage U _{imp}	4500 V
Rated operational voltage U _e	230 - 400 V

Connection

Cross-section rigid conductor	16 mm ²
Connector/plug type	Phase busbar with fork

Capacity

Number of modules	54
-------------------	----

Sustainability

Halogen free	Yes
REACH-SVHC free	Yes
RoHS conform	Yes