


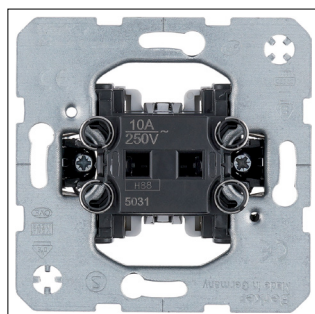

5031



Rocker push-button NO contact Module insert

Technical Features

Electric current

Switching current	10 A
Momentary contact current	10 A

Voltage

Rated voltage	250 V
---------------	-------

Frequency

Frequency	50 - 60 Hz
-----------	------------

Architecture

Control/operation element	Rocker
Number of poles	1

Materials

Material	Metal Plastic
Transparent	No

Dimensions

Height	70.80 mm
Width	70.80 mm
Depth	41.60 mm
Built-in depth	30 mm
Built-in depth flush-mounted boxes	35 mm

Installation, mounting

Mounting on	Flush mounting
-------------	----------------

Controls and indicators

Number of buttons	1
Type of push button	Single push button
With feedback signal contact	No

Safety

Ingress Protection (IP) class	IP20
Impact resistance IK	IK07

Accessories

Has labelling field	No
---------------------	----

Texts

Imprint	Without imprint
Installation mode	With spreader claws
Lighting	For lighting and monitoring circuit
Switch mode	Normally open contact
Type of connection	With plug-in terminals

Suitable for

K.x / Q.x / R.x / S.x/B.x

Sustainability

Halogen free	Yes
RoHS conform	Yes