


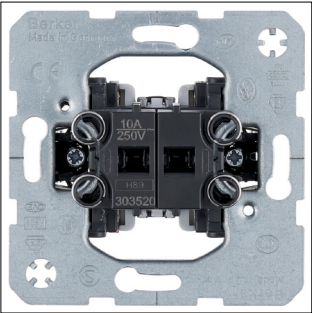

303520



**Blind switch 1pole, blind control**

**Technical Features**

**Controls and indicators**

|                            |               |
|----------------------------|---------------|
| Venetian blind switch type | 1-pole switch |
|----------------------------|---------------|

**Materials**

|                |                  |
|----------------|------------------|
| Surface finish | Matt             |
| Material       | Metal<br>Plastic |
| Treatment      | Untreated        |

**Voltage**

|               |       |
|---------------|-------|
| Rated voltage | 250 V |
|---------------|-------|

**Electric current**

|                   |                        |
|-------------------|------------------------|
| Switching current | 10 AX (100W LED (SBL)) |
| Switching current | 10 A                   |

**Safety**

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP20 |
|-------------------------------|------|

**Texts**

|                    |                                                                      |
|--------------------|----------------------------------------------------------------------|
| Switch mode        | With mechanical and electrical interlock to prevent mutual switch-on |
| Type of connection | With plug-in terminals                                               |
| Installation mode  | With spreader claws                                                  |

**Suitable for**

|                                                           |
|-----------------------------------------------------------|
| B.3 / B.7 / K.1 / K.5 / Q.1 / Q.3 / Q.7 / R.1 / R.3 / S.1 |
|-----------------------------------------------------------|

**Sustainability**

|              |     |
|--------------|-----|
| Halogen free | Yes |
| RoHS conform | Yes |