


303520

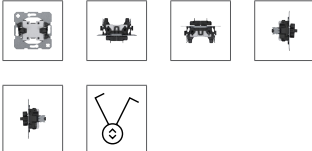

**Blind switch 1pole, blind control**

**Technical Features**

**Controls and indicators**

Venetian blind switch type 1-pole switch

**Materials**

Surface finish Matt  
 Material Metal  
Plastic  
 Treatment Untreated

**Voltage**

Rated voltage 250 V

**Electric current**

Switching current 10 AX (100W LED (SBL))  
 Switching current 10 A

**Safety**

Ingress Protection (IP) class IP20

**Texts**

Switch mode With mechanical and electrical interlock to prevent mutual switch-on  
 Type of connection With plug-in terminals  
 Installation mode With spreader claws

**Suitable for**

B.3 / B.7 / K.1 / K.5 / S.1

**Sustainability**

Halogen free Yes  
 RoHS conform Yes