


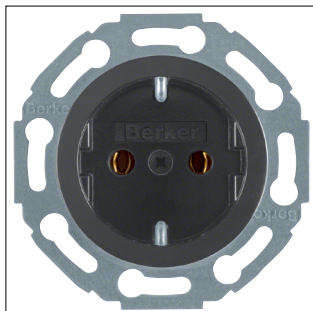

474521

SCHUKO soc. out., mounting orient. var. in 45° steps, 1930/glass, black glossy

Technical Features

Electric current

Rated current	16 A
---------------	------

Voltage

Rated voltage	250 V
Nominal voltage	250 - 250 V

Frequency

Frequency	50 - 60 Hz
-----------	------------

Materials

Colour	Black
RAL code	9005
Surface finish	Glossy
Material	Duroplastic
Treatment	Untreated

Dimensions

Height	71 mm
Width	71 mm
Depth	42 mm
Number of units	1
Built-in depth flush-mounted boxes	31 mm
Built-in depth	32 mm

Connection

Connector/plug type	Plug-in terminal
---------------------	------------------

Installation, mounting

Mounting on	Flush mounting
-------------	----------------

Connectivity

Type of connection	Plug-in connection
Mounting type	Screw mounting Claw mounting

Equipment

Connector/plug type socket outlet	SCHUKO
Rotated central insert	Yes
With hinged lid	No
With round protective earth pin	No
With signal lamp	No
With lock	No

Accessories

Has labelling field	No
---------------------	----

Capacity

Number of modules	1
-------------------	---

Safety

With enhanced contact protection	No
Impact resistance IK	IK02
Ingress Protection (IP) class	IP20

Functions

With orientation lighting	No
With function lighting	No

Product Datasheet

474521

Texts

Imprint	Without imprint
Cover	Central cover plate
Protection	Without enhanced contact protection
Type of connection	With plug-in terminals

Suitable for

Serie 1930 / Serie Glas

Sustainability

Halogen free	Yes
RoHS conform	Yes