


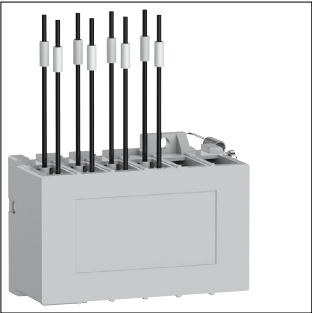

HSX042H

Auxilliary Switch 4NO+4NC HWS (AX)

Technical Features

Electric current	
Rated current 230 V AC15	2 A
Connectivity	
Mounting type	Click mounting
Frequency	
Frequency	50 - 60 Hz
Use conditions	
Storage/transport temperature	-40 - 70 °C
Sustainability	
Halogen free	Yes
REACH-SVHC free	Yes
RoHS conform	Yes