


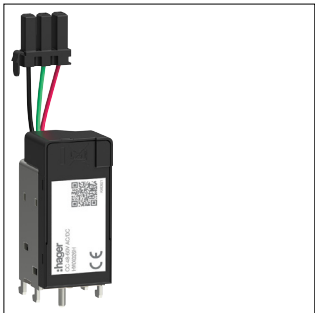

HWX026H

Closing coil 48-60V AC/DC (CC)

Technical Features

Power

Inrush power absorbed	250 VA
Operating consumption	5 VA
Power dissipation at IN	5 W

Safety

Ingress Protection (IP) class	IP4X
-------------------------------	------

Use conditions

Operating temperature	-25 - 70 °C
-----------------------	-------------

Voltage

Command voltage AC	48 - 60 V
Command voltage DC	48 - 60 V
Rated insulation voltage U_i	480 V
Rated impulse withstand voltage U_{imp}	6000 V
Overvoltage category according to IEC 60947-1	2

Sustainability

Halogen free	Yes
REACH-SVHC free	Yes
RoHS conform	Yes